

Spacer Blocks


Tapped / Through Holes

■ **Features:** Block to adjust positions as a spacer.

Spacer Blocks



RoHS10

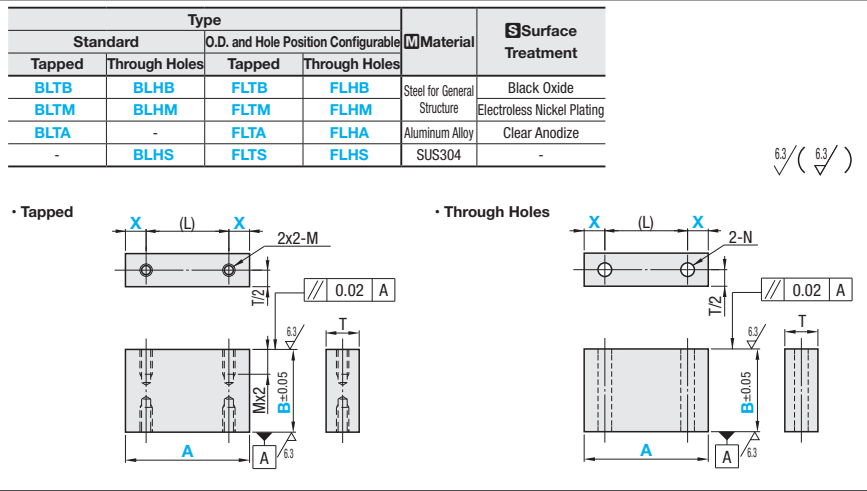

Standard

Part Number	Type	No.	A Selection	B 5mm Increment		T			L	M	N
				Tapped	Through Holes	BLTB BLTM	BLHB BLHM	BLTA BLHS			
Tapped SS400 BLTB BLTM	Through Holes SS400 BLHB BLHM	4	32	15~80	10~50	9	10	L=A-(2X)	4	4.5	
A6063 BLTA	SUS304 BLHS	5	38			12	12		5	5.5	
		6	60			16	15		6	6.5	
		8	75			22	20		8	9	
			100								
			125								

* X Dimension Details			
A	No.4, 5	No.6	No.8
32	6	7	8
38	6.5	8	9
60	10	10	10
100	12.5	12.5	12.5

⚠ Taps go through when B≤4xM. When B≤6xM, the tap pilots go through.



O.D. and Hole Position Configurable Type

Part Number	Type	No.	A 1mm Increment	B 1mm Increment		X 1mm Increment	T			L	M	N
				Tapped	Through Holes		FLTB FLTM	FLHB FLHM	FLTA FLHA			
Tapped SS400 FLTB FLTM	Through Holes SS400 FLHB FLHM	4	32	15~80	10~50	6~35	9	10	L=A-(2X)	4	4.5	
A6063 FLTA	A6063 FLHA	5	38				12	12		5	5.5	
SUS304 FLTS	SUS304 FLHS	6	60				16	15		6	6.5	
		8	75				22	20		8	9	
			125									

⚠ Taps go through when B≤4xM. When B≤6xM, the tap pilots go through. ⚠ A-(2X)≥16

Ordering Example	Part Number	A	B	X
	BLTB4	38	25	
	BLHM8	60	30	
	FLTM6	78	35	30

EX Example

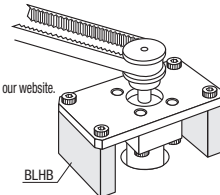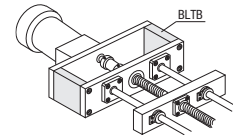


Alterations	Code	Spec.
Omits Taps on One Side	NC	Omits tapped holes on one side. Ordering Code NC ⚠ Applicable to Tapped Type only.

EX Example

Combination of these app. examples can be selected on our website.
Selection Procedure Details P.87

e-Catalog Search Keyword #MA91 Search
* Enter the search keyword in the search box on e-Catalog. The search result will be shown in "Modular Assembler" area.

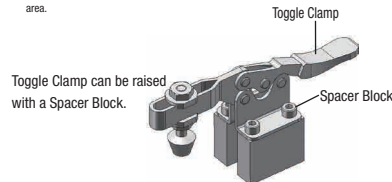

Standard

Part Number	Type	No.	A	Unit Price					
				Tapped			Through Holes		
				Min. B - 30	B35-60	B65-80	Min. B - 30	B35-60	B65-80
SS400D Black Oxide BLTB BLHB	4		32, 38						
			60, 75						
			100, 125						
	5		32, 38						
			60, 75						
			100, 125						
	6		32, 38						
			60, 75						
			100, 125						
	8		32, 38						
			60, 75						
			100, 125						
SS400D Electroless Nickel Plating BLTM BLHM	4		32, 38						
			60, 75						
			100, 125						
	5		32, 38						
			60, 75						
			100, 125						
	6		32, 38						
			60, 75						
			100, 125						
	8		32, 38						
			60, 75						
			100, 125						
A6063 Clear Anodize BLTA	4		32, 38						
			60, 75						
			100, 125						
	5		32, 38						
			60, 75						
			100, 125						
	6		32, 38						
			60, 75						
			100, 125						
	8		32, 38						
			60, 75						
			100, 125						
SUS304 BLHS	4		32, 38						
			60, 75						
			100, 125						
	5		32, 38						
			60, 75						
			100, 125						
	6		32, 38						
			60, 75						
			100, 125						
	8		32, 38						
			60, 75						
			100, 125						

O.D. and Hole Position Configurable Type

Part Number	Type	No.	A	Unit Price					
				Tapped			Through Holes		
				Min. B - 34	B35-64	B65-80	Min. B - 34	B35-64	B65-80
SS400D Black Oxide FLTB FLHB	4		32~38						
			39~99						
			100~125						
	5		32~38						
			39~99						
			100~125						
	6		32~38						
			39~99						
			100~125						
	8		32~38						
			39~99						
			100~125						
SS400D Electroless Nickel Plating FLTM FLHM	4		32~38						
			39~99						
			100~125						
	5		32~38						
			39~99						
			100~125						
	6		32~38						
			39~99						
			100~125						
	8		32~38						
			39~99						
			100~125						
A6063 Clear Anodize FLTA FLHA	4		32~38						
			39~99						
			100~125						
	5		32~38						
			39~99						
			100~125						
	6		32~38						
			39~99						
			100~125						
	8		32~38						
			39~99						
			100~125						
SUS304 FLTS FLHS	4		32~38						
			39~99						
			100~125						
	5		32~38						
			39~99						
			100~125						
	6		32~38						
			39~99						
			100~125						
	8		32~38						
			39~99						
			100~125						