

# Phillips Pan Head Screws with Captured Washer


Single Item Sale

Phillips Pan Head Screws with Captured Washer SW+JIS W Captured



RoHS10

**NSET**  
**SCBJ**

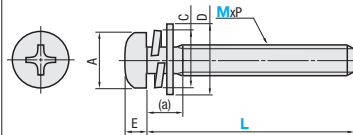

**NSET**

<b>Screw</b>	Material: SWCH Equivalent
<b>Washers</b>	Spring Washer JIS B 1251 Flat Washer JIS B 1256
<b>Surface Treatment</b>	Trivalent Chromate

**SCBJ**

<b>Screw</b>	Material: SUS304 Equivalent
<b>Washers</b>	Spring Washer JIS B 1251 Flat Washer JIS B 1256

MxP	A	E	C (Max.)	D	(a)	Phillips No.
2 x0.4	3.5	1.3	4.0	6.0	2.1	1
2.5x0.45	4.5	1.7	4.8	6.5	2.7	1
2.6x0.45	4.5	1.7	4.8	7.5	2.7	1
3 x0.5	5.5	2.0	5.5	8.0	3.0	2
4 x0.7	7.0	2.6	7.0	10.0	4.4	2
5 x0.8	9.0	3.3	8.5	12.0	5.4	2
6 x1.0	10.5	3.9	11.5	13.0	6.9	3

Part Number	Type	M-L	NSET		SCBJ			
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate		
			1 - 99 pc(s)	100 - 500 pcs.	1 - 29 pc(s)	30 - 99 pcs.	100 - 149 pcs.	150 - 500 pcs.
2	-	4						
5	-	6						
8	-	8						
10	-	10						
2.5	-	4						
5	-	6						
8	-	8						
10	-	10						
2.6	-	4						
5	-	6						
6	-	8						
8	-	10						
10	-	12						
12	-	14						
14	-	16						
15	-	18						
16	-	20						
20	-	25						
25	-	30						
30	-	35						
40	-	45						
45	-	50						
4	-	5						
6	-	8						
8	-	10						
10	-	12						
12	-	14						
14	-	16						
16	-	18						
20	-	25						
25	-	30						
30	-	35						
35	-	40						
40	-	45						
45	-	50						
5	-	8						
10	-	12						
12	-	14						
14	-	16						
16	-	18						
20	-	25						
25	-	30						
30	-	35						
35	-	40						
40	-	45						
45	-	50						
6	-	10						
12	-	14						
14	-	16						
16	-	18						
20	-	25						
25	-	30						
30	-	35						
35	-	40						
40	-	45						
45	-	50						


NSET  
SCBJ

Phillips Pan Head Screws with Captured Washer SW+JIS Compact W Captured



RoHS10

**PSET**  
**PSETS**

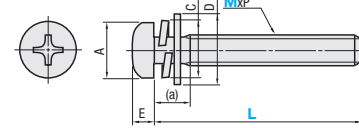

**PSET**

<b>Screw</b>	Material: SWCH Equivalent
<b>Washers</b>	Spring Washer JIS B 1251 Flat Washer JIS B 1256
<b>Surface Treatment</b>	Trivalent Chromate

**PSETS**

<b>Screw</b>	Material: SUS304 Equivalent
<b>Washers</b>	Spring Washer JIS B 1251 Flat Washer JIS B 1256

MxP	A	E	C (Max.)	D	(a)	Phillips No.
3x0.5	5.5	2.0	5.5	6.0	3.0	2
4x0.7	7.0	2.6	7.0	8.0	4.4	2
5x0.8	9.0	3.3	8.5	10.0	5.4	2
6x1.0	10.5	3.9	11.5	11.5	6.9	3

Part Number	Type	M-L	PSET		PSETS	
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
			1 - 29 pc(s)	30 - 99 pcs	100 - 149 pcs	150 - 500 pcs.
3	-	6				
8	-	10				
12	-	15				
4	-	6				
8	-	10				
12	-	15				
5	-	8				
10	-	12				
12	-	15				
6	-	10				
12	-	15				
15	-	20				


PSET  
PSETS

Phillips Pan Head Screws with Captured Washer SW Captured



RoHS10

**WSET**  
**WSETS**

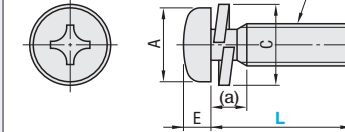

**WSET**

<b>Screw</b>	Material: SWCH Equivalent
<b>Washers</b>	Spring Washer JIS B 1251
<b>Surface Treatment</b>	Trivalent Chromate

**WSETS**

<b>Screw</b>	Material: SUS304 Equivalent
<b>Washers</b>	Spring Washer JIS B 1251


MxP	A	E	C (Max.)	(a)	Phillips No.
3x0.5	5.5	2.0	5.5	2.4	2
4x0.7	7.0	2.6	7.0	3.5	2
5x0.8	9.0	3.3	8.5	4.3	2
6x1.0	10.5	3.9	11.5	5.1	3

Phillips Hex Head Screws with Captured Washer



RoHS10

**BSET**  
**SBSET** (Stainless Steel)

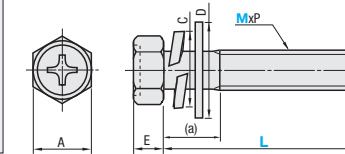

**BSET**

<b>Screw</b>	Material: Structural Alloy Steel Screw: JIS 0209 (6g)
<b>Washers</b>	Spring Washer JIS B1251 Flat Washer JIS B1256
<b>Surface Treatment</b>	Trivalent Chromate

**SBSET**

<b>Screw</b>	Material: SUS304 Equivalent *Strength Class A2-50 Equivalent Screw: JIS 0209 (6g)
<b>Washers</b>	Spring Washer JIS B1251 Flat Washer JIS B1256
<b>Surface Treatment</b>	Barrel, Passivated

MxP	A	E	C	D	(a)
4x0.7	7	2.8	7.0	10	4.4
5x0.8	8	3.5	8.5	12	5.2
6x1.0	10	4.0	11.5	13	6.3
8x1.25	13	5.5	14.5	18	8.4

(a) is the max length (reference) between head surface and the complete thread.



Ordering Example  
Part Number  
**WSET5-10**  
**WSET4-8**

Part Number	Type	M-L	WSET				WSETS			
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
			1 - 29 pc(s)	30 - 99 pcs.	100 - 199 pcs.	200 - 500 pcs.	1 - 29 pc(s)	30 - 99 pcs.	100 - 199 pcs.	200 - 500 pcs.
3	-	6								
8	-	10								
12	-	15								
4	-	8								
10	-	12								
15	-	20								
5	-	8								
10	-	12								
15	-	20								
6	-	10								
12	-	15								
15	-	20								

Part Number	Type	M-L	BSET		SBSET		Part Number	Type	M-L	BSET		SBSET	
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
			1 - 99 pc(s)	100 - 500 pcs.	1 - 99 pc(s)	100 - 500 pcs.				1 - 99 pc(s)	100 - 300 pcs.	1 - 99 pc(s)	100 - 500 pcs.
BSET	4-8	10					BSET	6-20	25				
SBSET	12	14					SBSET	30	35				
	16	20						40	45				
	25	30						50	55				
	35	40						60	65				
	45	50						70	75				
BSET	5-10	12					BSET	8-12	14				
SBSET	16	20					SBSET	25	30				
	30	35						40	45				
	40	45						50	55				
	50	60						65	70				
BSET	6-10	12					BSET	16					
SBSET	14	16					SBSET	25	30				
	20	25						35	40				
	30	35						45	50				
	40	45						55	60				
	50	60						65	70				
	60	75						85	100				



Ordering Example  
Part Number  
**SCBJ6-10**  
**PSET3-6**