

One-Touch Block Chains

Curved

Registration of a design pending

■ **Features:** Side Flexing Table Top Chains with the world's smallest bending radius. Chain removal is easy, and available for not only return transfer but horizontal circulation transfer.

Part Number		Specification	Material	Color	Sliding Friction Coefficient f1	Operating Temp. (°C)
Standard	Attachment					
CHEC	CHECA	General Use	POM	White	0.14~0.18	-5~65
CHECS	CHEACS	Extra Low Friction	POM + Lubricant	Cream	0.12~0.15	-5~65
CHECC	CHEACC	Conductivity, Heat Resistant	POM + Glass Fiber	Black	0.20~0.24	-20~120
CHECY	CHEACY	Chemical Resistant	Fluororesin	Translucent	0.18~0.22	-20~80

■ **Standard**

CHEC
CHECS
CHECC
CHECY

■ **Attachment**

CHECA
CHEACS
CHEACC
CHEACY

■ **Allowable Tension and Reference Weight**

Nominal	Allowable Tension (N)				Reference Weight (kg/m)
	CHEC CHECA	CHECS CHEACS	CHECC CHEACC	CHECY CHEACY	
60	350	310	390	310	0.47

⚠ How to Select Applicable Chains: P.1578
 ⚠ Since the bending angle of chain is predetermined, specify the mating sprocket with the number of teeth, 14 or more.
 ⚠ Use CHEER, CHEERS (on P.1585) for sprockets at returning site. P.1585
 ⚠ Use with Corner Discs (on P.1585).
 ⚠ For attachment, use with Flap Plates (P.1582) in combination.
 ⚠ For Allowable Tension and Corrosion Resistance List, see P.1577
 ⚠ May have scratches when links are removed.

Part Number		Pitch	W	H1	H2	Bending Radius	
Type	Nominal						
Standard CHEC CHECS CHECC CHECH CHECY	Attachment CHECA CHEACS CHEACC CHEACH CHEACY	60	19.05	36	17.5	12	R67
		Number of Links Configurable 1~99					
		Number of Links Fixed 20 100					
		Number of Links Fixed (disconnected) 20-NA					

⚠ For Number of Links 20NA (disconnected), links are not connected. Use them to adjust amount or for repairing.

■ **Number of Links Configurable**

Part Number	Unit Price (Unit : 20 Links)				Unit Price (Unit : 100 Links)					
	Type	Nominal	CHEC CHECA	CHECS CHEACS	CHECC CHEACC	CHECY CHEACY	CHEC CHECA	CHECS CHEACS	CHECC CHEACC	CHECY CHEACY
Standard CHEC CHECS CHECC CHECH CHECY	Attachment CHECA CHEACS CHEACC CHEACH CHEACY	60								


■ **Number of Links Configurable**

Part Number	Unit Price (Unit : 1 Link)					
	Type	Nominal	CHEC CHECA	CHECS CHEACS	CHECC CHEACC	CHECY CHEACY
Standard CHEC CHECS CHECC CHECH CHECY	Attachment CHECA CHEACS CHEACC CHEACH CHEACY	60				

■ **How to Order**
 Please order in combination with "Number of Links Fixed Type" and "Number of Links Fixed Type (disconnected)" or "Number of Links Configurable Type".

Ordering Example

Part Number	-	Number of Links
CHEC60	-	473
CHEAC60	-	20-NA

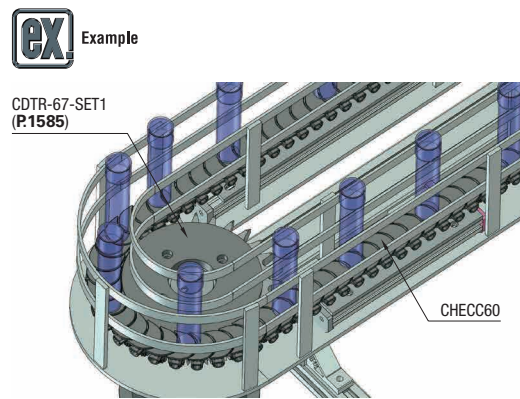

One-Touch Flat Chains

Curved

Registration of a design pending

■ **Features:** Side flexing chains capable of wide surface transfer. Returning and horizontal circulation transfers are both available with the world's smallest bending radius.

Part Number		Specification	Material	Color	Sliding Friction Coefficient f1	Operating Temp. (°C)
Set	Flap					
CHEFR	CHEFRP	General Use	POM	White	0.14~0.18	-5~65
CHEFRS	CHEFRPS	Extra Low Friction	POM + Lubricant	Cream	0.12~0.15	-5~65
CHEFRC	CHEFRPC	Conductivity, Heat Resistant	POM + Glass Fiber	Black	0.20~0.24	-20~120
CHEFRY	CHEFRPY	Chemical Resistant	Fluororesin	Translucent	0.18~0.22	-20~80

■ **Thin Table Top Chain Set**

CHEFR
CHEFRS
CHEFRC
CHEFRY

■ **Flap Plate**

CHEFRP
CHEFRPS
CHEFRPC
CHEFRPY

■ **Allowable Tension and Reference Weight**

Nominal	Allowable Tension (N)				Reference Weight (kg/m)
	CHEFR CHEFRP	CHEFRS CHEFRPS	CHEFRC CHEFRPC	CHEFRY CHEFRPY	
60	350	310	390	310	0.84

⚠ How to Select Applicable Chains: P.1578
 ⚠ Since the bending angle of chain is predetermined, specify the mating sprocket with the number of teeth, 14 or more.
 ⚠ Use CHEER, CHEERS (on P.1585) for sprockets at returning site. P.1585
 ⚠ A set comes with Flap Plates and One-Touch Block Chains Attachment Type (P.1581).
 ⚠ Use with Corner Discs (on P.1585).
 ⚠ For Allowable Tension and Corrosion Resistance List, see P.1577
 ⚠ May have scratches when links are removed.

■ **Number of Links Fixed (Set)**

Part Number	Type	Nominal	W	Number of Links	Pitch	L	H1	H2	Bending Radius
				Number of Links Configurable 2~98					
				Number of Links Fixed 20 100					
				Number of Links Fixed (disconnected) 20-NA					

⚠ For Number of Links 20NA (disconnected), links are not connected. Use them to adjust amount or for repairing.

■ **Number of Links Configurable (Set)**

Part Number	Type	Nominal	W	Unit Price (Unit : 1 Link)			
				CHEFR	CHEFRS	CHEFRC	CHEFRY
Set CHEFR CHEFRS CHEFRC CHEFRY	60	100					

■ **Number of Links Fixed (Flap)**

Part Number	Type	Nominal	A	Number of Links	Unit Price (Unit : 20 Links)			
					CHEFRP	CHEFRPS	CHEFRPC	CHEFRPY
Flap CHEFRP CHEFRPS CHEFRPC CHEFRPY	60	100	Number of Links Fixed 20					

■ **How to Order**
 Please order in combination with "Number of Links Fixed Type" and "Number of Links Fixed Type (disconnected)" or "Number of Links Configurable Type".

Ordering Example

Part Number	-	A	-	Number of Links
CHEFR60	-	100	-	350
CHEFRPS60	-	100	-	20-NA

