


ONE-TOUCH FITTINGS


-ONE TOUCH PLUG TYPE / HIGH PRESSURE AND HIGH TEMPERATURE TYPE (HEAT RESISTANCE 60°C/ 80°C)-

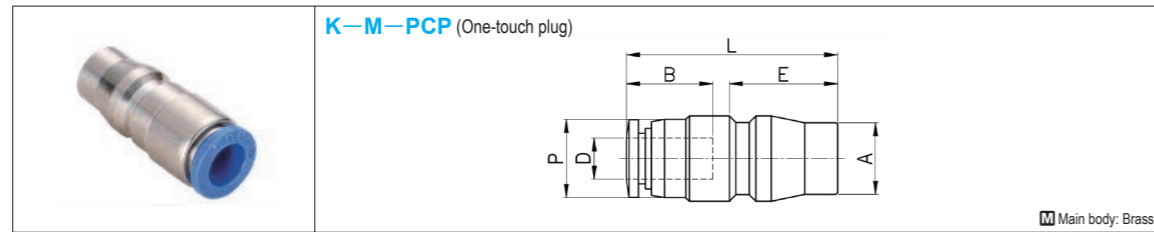

K-M-PCP (One-touch plug)

Main body: Brass


| Max. pressure MPa (kgf/cm ²) | Usable temp. range | D | P | A | L | E | B | Part Number | | Unit Price 1-10 pcs |
|---|-----------------------|----|------|------|------|------|------|----------------|-----|------------------------|
| | | | | | | | | Type | No. | |
| 0.99 (9.9) | 32-140°F/ 0-60°C | 4 | 10 | 10.9 | 31 | 16.3 | 14.8 | K-M-PCP | 04 | Quotation |
| | | 6 | 11.9 | | 31.7 | | 17.4 | | 06 | |
| | | 8 | 14 | | 34.9 | | 18.4 | | 08 | |
| | | 10 | 16 | | 42.4 | | 19.7 | | 10 | |
| | | 12 | 19 | | 45.4 | | 21.9 | | 12 | |

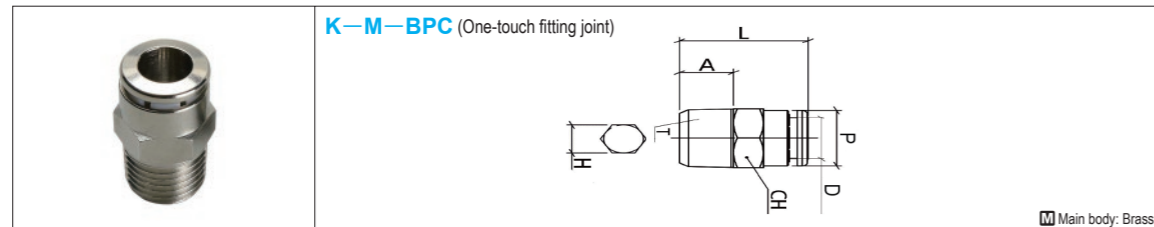

K-M-BPC (One-touch fitting joint)

Main body: Brass

| Max. pressure MPa (kgf/cm ²) | Usable temp. range | D | T | P | A | L | CH | H | Part Number | | Unit Price |
|---|-----------------------|----|------|----|----|------|-------|---|----------------|-------|------------|
| | | | | | | | | | Type | No. | |
| 1.38 (16) | -4-175°F/ 20-80°C | 6 | R1/8 | 12 | 8 | 21 | 12 | 4 | K-M-BPC | 06R01 | Quotation |
| | | | R1/4 | | 10 | 20 | 06R02 | | | | |
| | | 8 | R1/8 | 14 | 8 | 26 | 14 | 5 | | 08R01 | |
| | | | R1/4 | | 10 | 24 | 08R02 | | | | |
| | | 10 | R3/8 | 16 | 11 | 22 | 17 | 6 | | 08R03 | |
| | | | R1/4 | | 10 | 31 | 16 | | | 10R02 | |
| | | | R3/8 | | 11 | 26 | 17 | | | 10R03 | |
| | | | R1/2 | | 14 | 26.5 | 22 | | | 10R04 | |
| | | 12 | R1/4 | 19 | 10 | 33 | 19 | 6 | | 12R02 | |
| | | | R3/8 | | 11 | 29.5 | 19 | | | 12R03 | |
| | | | R1/2 | | 14 | 27 | 22 | | | 12R04 | |

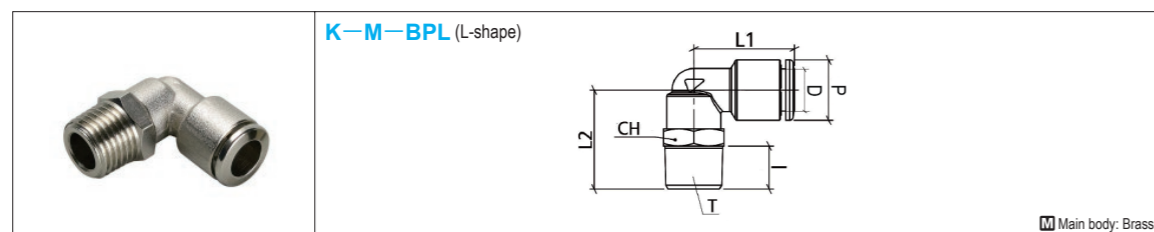

K-M-BPL (L-shape)


Main body: Brass

| Max. pressure MPa (kgf/cm ²) | Usable temp. range | D | T | P | A | L | CH | H | Part Number | | Unit Price |
|---|-----------------------|----|------|----|----|------|------|-------|----------------|-------|------------|
| | | | | | | | | | Type | No. | |
| 1.38 (16) | -4-175°F/ 20-80°C | 6 | R1/8 | 12 | 8 | 21 | 20.5 | 13 | K-M-BPL | 06R01 | Quotation |
| | | | R1/4 | | 10 | 23 | 14 | 06R02 | | | |
| | | 8 | R1/8 | 14 | 8 | 20.5 | 13 | 14 | | 08R01 | |
| | | | R1/4 | | 10 | 23 | 14 | | | 08R02 | |
| | | 10 | R3/8 | 16 | 11 | 24.5 | 17 | 16 | | 08R03 | |
| | | | R1/4 | | 10 | 25.5 | 16 | | | 10R02 | |
| | | | R3/8 | | 11 | 27 | 17 | | | 10R03 | |
| | | | R1/2 | | 14 | 30 | 22 | | | 10R04 | |
| | | 12 | R1/4 | 19 | 10 | 28 | 20 | 20 | | 12R02 | |
| | | | R3/8 | | 11 | 28.5 | 20 | | | 12R03 | |
| | | | R1/2 | | 14 | 31.5 | 22 | | | 12R04 | |

Order **Part Number** **K-M-PCP-04** **K-M-BPC-06R01** **K-M-BPL-06R01** Days to Ship **Quotation** Price **Quotation**

STEEL COUPLINGS


-STANDARD TYPE (HEAT RESISTANCE 60°C)-

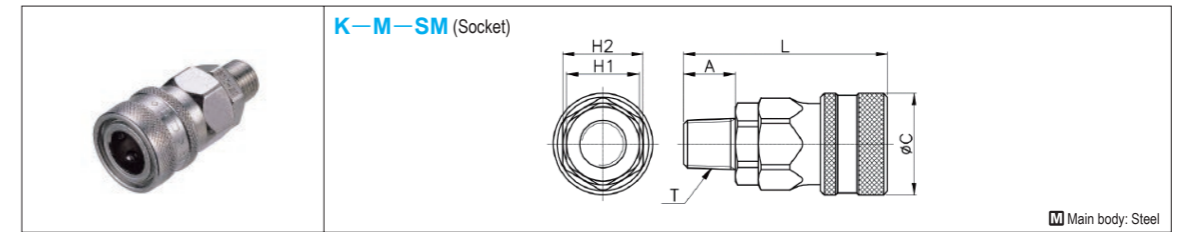

K-M-SM (Socket)

Main body: Steel

| Max. pressure MPa (kgf/cm ²) | Usable temp. range | φC | T | L | A | H1 (Hex) | H2 (Hex) | Part Number | | Unit Price |
|---|-----------------------|----|-------|------|------|-------------|-------------|---------------|-----|------------|
| | | | | | | | | Type | No. | |
| 0.99 (9.9) | 32-140°F/ 0-60°C | 26 | R 1/4 | 54 | 13.5 | 19 | 21 | K-M-SM | 20 | Quotation |
| | | | R 3/8 | 55.5 | 14 | | | | 30 | |
| | | | R 1/2 | 58 | 15.5 | | | | 40 | |

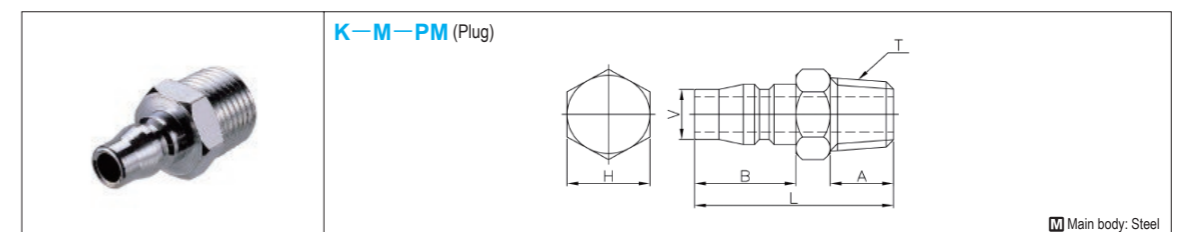

K-M-PM (Plug)

Main body: Steel

| Max. pressure MPa (kgf/cm ²) | Usable temp. range | T | L | A | B | H | V | Part Number | | Unit Price |
|---|-----------------------|-------|------|------|------|----|------|---------------|-----|------------|
| | | | | | | | | Type | No. | |
| 0.99 (9.9) | 32-140°F/ 0-60°C | R 1/4 | 40 | 13.5 | 20.5 | 14 | 10.9 | K-M-PM | 20 | Quotation |
| | | R 3/8 | 42 | 14.5 | | 17 | | | 30 | |
| | | R 1/2 | 42.5 | 15 | | 21 | | | 40 | |

Order **Part Number** **K-M-SM30** **K-M-PM30** Days to Ship **Quotation** Price **Quotation**