

**NEW**


SUCTION CUP

# SUCTION CUP (EP SPONGE TYPE)

■ Suction Cup (EP Sponge type)



VC-ES

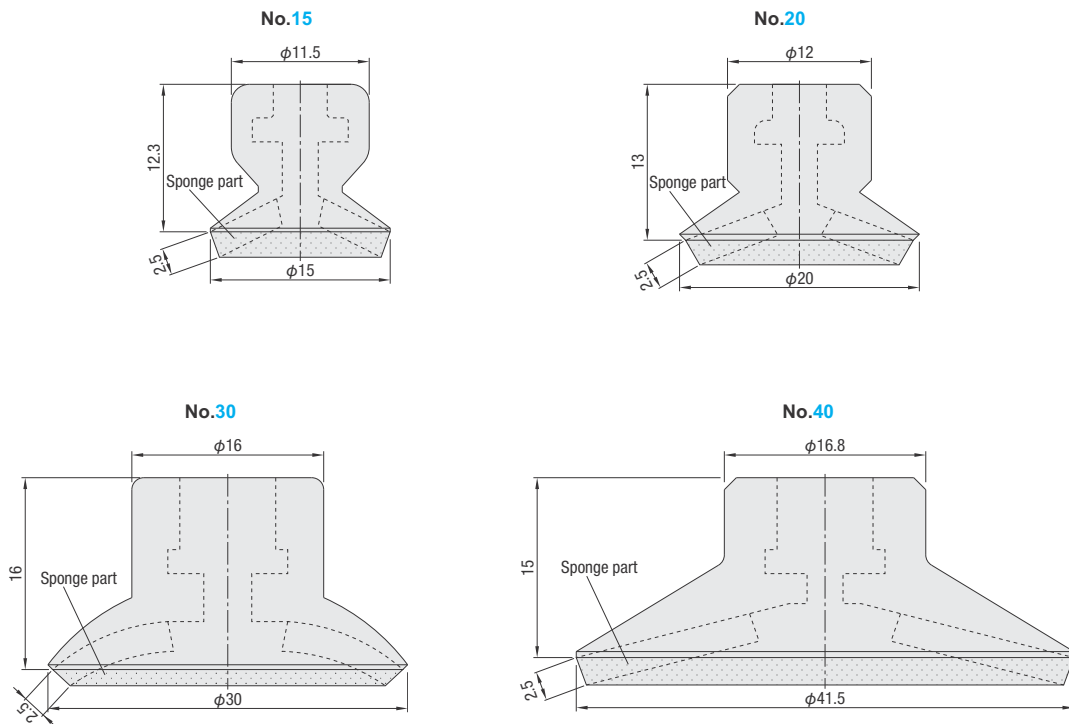

**M** Body: Silicone  
 Sponge: EDPM silicone  
**H** Shore A50~70  
 Specification Temperature -70°C~200°C  
 Maximum Operating Temperature 80°C

Applicable metal fittings	Mounting type	Cup dia.	Weight (g)*1	Part Number		Unit Price
				Type	No.	1~30 pcs
VC-KNG7 VC-KNGB7	Embedded type	15	1	VC-ES	15	Quotation
		20	1		20	
VC-KNG11 VC-KNGB11		30	3		30	
		41.5	5		40	

\*1 The weight is an approximate value which serves only as a guideline.



Order

Part Number  
VC-ES30



Days to Ship

Quotation



Price

Quotation