

FLAT SUCTION CUP (SILICONE / NITRILE / FLUORINE)

VC-SP (Flat)

No.4

No.6

No.8

No.10

No.12

No.14

No.15

No.20

No.25

No.30

No.35

No.40

No.45

No.50

Material symbol	M Material	H Hardness	Usable temperature range	Color
S	Silicone rubber	Shore A50-70	-70~200°C	White
N	Nitrile rubber	Shore A50-70	-10~99°C	Blue
F	Fluorine rubber	Shore A60-80	-10~230°C	Black

Applicable metal fittings	Mounting type	Cup dia.	Weight (g) ^{*1}	Part Number		Material symbol	Unit Price 1~30 pcs		
				Type	No.		S	N	F
VC-KNG7 VC-KNGB7	Embedded type	4	1	VC-SP (Flat)	4	S (Silicone)			
		6	1		6				
		8	1		8				
		10.5	1		10				
		12	1		12				
		14	1		14				
		15	1		15				
		20	1		20				
		25	2		25				
		30	3		30				
VC-KNG11 VC-KNGB11	Embedded type	35	4	35		N (Nitrile)			
		41.5	5	40					
		45	5	45					
				50					

*1 The weight is an approximate value which serves only as a guideline.



Order

Part Number

VC-SP15

Material symbol

S



Days to Ship

Quotation




Price

Quotation


REMOVAL RELATED PRODUCTS

BELLOWS SUCTION CUP (SILICONE / NITRILE / FLUORINE)




VC—HSP (Bellows)

 
No.6—2




No.8—3

 


No.10—3

 


No.12—3

 


No.15—3

 


No.20—3

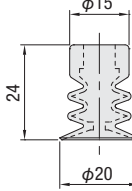

No.30—3A

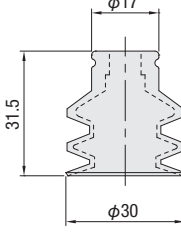

No.40—3A

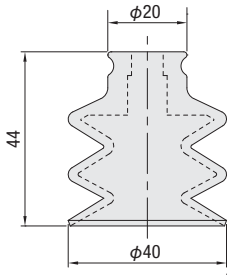

Material symbol	M Material	H Hardness	Usable temp. range	Color
S	Silicone rubber	Shore A50~70	-70~200°C	White
N	Nitrile rubber	Shore A50~70	-10~99°C	Blue
F	Fluorine rubber	Shore A60~80	-10~230°C	Black


Applicable metal fittings	Mounting type	Cup dia.	Weight (g) ^{*1}	Part Number		Material symbol	Unit Price 1~30 pcs		
				Type	No.		S	N	F
VC—KNG11 VC—KNGB11	Embedded type	6	1	VC—HSP (Bellows)	6—2	S (Silicone)			
		8	1		8—3				
		10	2		10—3	N (Nitrile)			
		12	2		12—3				
		15	2		15—3	F (Fluorine)			
		20	2		20—3				
		30	4		30—3A				
		40	15		40—3A				
Quotation									

*1 The weight is an approximate value which serves only as a guideline.

Order Part Number — Material symbol
VC—HSP20—3 — N

Days to Ship Quotation

Price Quotation

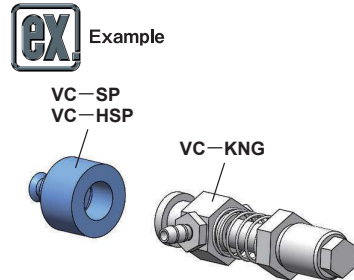

• Insert the tip of the suction bracket (VC—KNG) to the back of the suction cup.