


ROLLER CARRIERS / BALL CARRIERS

Roller Carriers

RoHS10

CORO
COROU

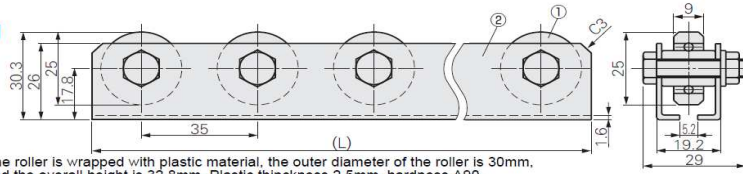

① COROU The roller is wrapped with plastic material, the outer diameter of the roller is 30mm, and the overall height is 32.8mm. Plastic thickness 2.5mm. hardness A90.

② Dimension insides are reference values. ③ CORO Loading bearing : 20Kg/Piece


① M Mat'l SS400 ② M Mat'l SPCC Hardness 55HRC~ (Carburizing and quenching)

L	Catalog No.	A 辘数	L	Catalog No.	A 辘数
(105)	CORO COROU	3	(560)	CORO COROU	16
(140)		4	(595)		17
(175)		5	(630)		18
(210)		6	(665)		19
(245)		7	(700)		20
(280)		8	(735)		21
(315)		9	(770)		22
(350)		10	(805)		23
(385)		11	(840)		24
(420)		12	(875)		25
(455)		13	(910)		26
(490)		14	(945)		27
(525)		15	(980)		28

Ball carriers

RoHS

GORO

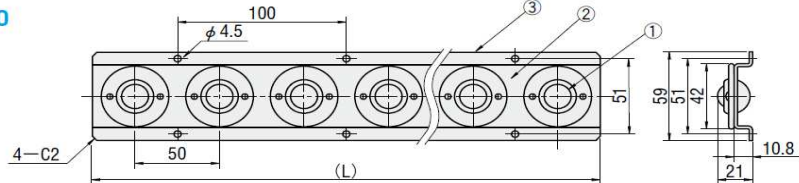

① (L) dimension is a value for reference only.

② Ball load resistance: 8kg/ball

① M SUJ2 ②③ M SPCC

L	Catalog No.	A Number of balls	Base unit price 1~9 pieces
(200)	GORO	4	Quotation
(300)		6	
(400)		8	
(500)		10	
(600)		12	
(700)		14	
(800)		16	
(900)		18	
(1000)		20	
(1100)		22	
(1200)	24		



Order

Catalog No.	A
CORO	10
GORO	8



Days to Ship

Quotation




Price

Quotation

Ball carriers (individual part)

RoHS

GORON

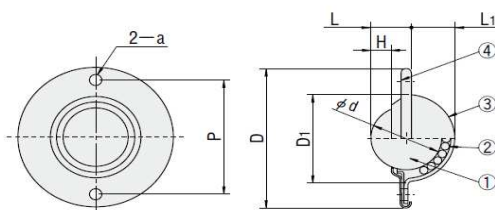

①② M SUJ2 ③ M SUS304 ④ M SPCC

Catalog No.	D	D ₁	L	L ₁	H	P	a	d	Load resistance N (kgf)	Weight (g)	Base unit price 1~9 pieces
GORON	41.3	24	10.2	(9.1)	4	30	3.5	15.875	78.4 (8)	45	Quotation



Order

Catalog No.
GORON



Example




Days to Ship

Quotation



Price

Quotation

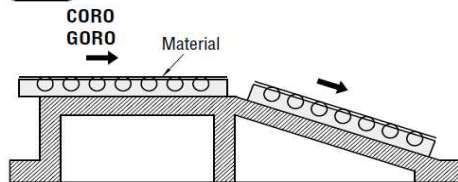

GORON

Conveyor bend point

